

Viti a testa troncoconica Phillips con rondella incorporata


Vendibili come elemento singolo

■ Viti a testa troncoconica Phillips con rondella incorporata
Rondella elastica-rondella piatta incorporata



RoHS10

NSET
SCBJ

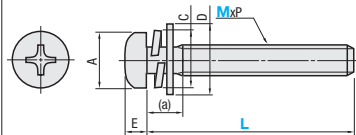

NSET

Vite **M** Materiale: JIS-SWCH Equiv.

Rondelle Rondella elastica JIS B 1251
Rondella piatta JIS B 1256

S Trattamento superficie Cromatura trivalente

SCBJ

Vite **M** Materiale: EN 1.4301 Equiv.

Rondelle Rondella elastica JIS B 1251
Rondella piatta JIS B 1256

MxP	A	E	C (Max)	D	(a)	Phil-lips N.
2 x0.4	3.5	1.3	4.0	6.0	2.1	1
2.5x0.45	4.5	1.7	4.8	6.5	2.7	1
2.6x0.45	4.5	1.7	4.8	7.5	2.7	1
3 x0.5	5.5	2.0	5.5	8.0	3.0	2
4 x0.7	7.0	2.6	7.0	10.0	4.4	2
5 x0.8	9.0	3.3	8.5	12.0	5.4	2
6 x1.0	10.5	3.9	11.5	13.0	6.9	3

Cod. comp.	Tipo	M-L	NSET		SCBJ			
			Prezzo unitario	Sconto volumi elevati	Prezzo unitario	Sconto volumi elevati		
			1 - 99 pz.	100 - 500 pz.	1 - 29 pz.	30 - 99 pz.	100 - 149 pz.	150 - 500 pz.
	2	- 4						
		5						
		6						
		8						
	2.5	- 4						
		5						
		6						
		8						
		10						
	2.6	- 4						
		5						
		6						
		8						
		10						
	3	- 5						
		6						
		8						
		10						
		12						
		14						
		15						
		16						
		20						
		25						
		30						
		35						
		40						
		45						
		50						
	4	- 5						
		6						
		8						
		10						
		12						
		14						
		16						
		20						
		25						
		30						
		35						
		40						
		45						
		50						
	5	- 8						
		10						
		12						
		14						
		16						
		20						
		25						
		30						
		35						
		40						
		45						
		50						
	6	- 10						
		12						
		14						
		16						
		20						
		25						
		30						
		35						
		40						
		45						
		50						


NSET
SCBJ

■ Viti a testa troncoconica Phillips con rondella incorporata
Rondella elastica-rondella compatta JIS incorporata



RoHS10

PSET
PSETS

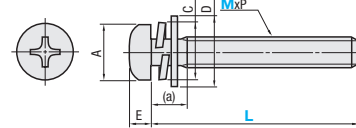

PSET

Vite **M** Materiale: JIS-SWCH Equiv.

Rondelle Rondella elastica JIS B 1251
Rondella piatta JIS B 1256

S Trattamento superficie Cromatura trivalente

PSETS

Vite **M** Materiale: EN 1.4301 Equiv.

Rondelle Rondella elastica JIS B 1251
Rondella piatta JIS B 1256

MxP	A	E	C (Max)	D	(a)	Phil-lips N.
3x0.5	5.5	2.0	5.5	6.0	3.0	2
4x0.7	7.0	2.6	7.0	8.0	4.4	2
5x0.8	9.0	3.3	8.5	10.0	5.4	2
6x1.0	10.5	3.9	11.5	11.5	6.9	3

Cod. comp.	Tipo	M-L	PSET				PSETS			
			Prezzo unitario	Sconto volumi elevati			Prezzo unitario	Sconto volumi elevati		
			1 - 29 pz.	30 - 99 pz.	100 - 149 pz.	150 - 500 pz.	1 - 29 pz.	30 - 99 pz.	100 - 149 pz.	150 - 500 pz.
	3	- 6								
		8								
		10								
		12								
	4	- 6								
		8								
		10								
		12								
		15								
	5	- 8								
		10								
		12								
		15								
	6	- 10								
		12								
		15								
		20								


PSET
PSETS

■ Viti a testa troncoconica Phillips con rondella incorporata
Rondella elastica incorporata



RoHS10

WSET
WSETS

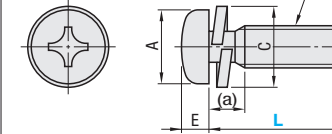

WSET

Vite **M** Materiale: JIS-SWCH Equiv.

Rondelle Rondella elastica JIS B 1251

S Trattamento superficie Cromatura trivalente

WSETS

Vite **M** Materiale: EN 1.4301 Equiv.

Rondelle Rondella elastica JIS B 1251


MxP	A	E	C (Max)	(a)	Phil-lips N.
3x0.5	5.5	2.0	5.5	2.4	2
4x0.7	7.0	2.6	7.0	3.5	2
5x0.8	9.0	3.3	8.5	4.3	2
6x1.0	10.5	3.9	11.5	5.1	3

■ Viti a testa esagonale Phillips con rondella incorporata



RoHS10

BSET
SBSET (Acciaio inox)

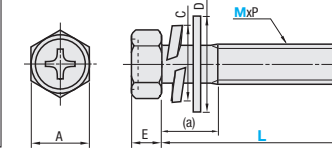

BSET

Vite **M** Materiale: Acciaio legato da costruzione

Vite: JIS 0209 (6g)

Rondelle Rondella elastica JIS B1251
Rondella piatta JIS B1256

S Trattamento superficie Cromatura trivalente

SBSET

Vite **M** Materiale: EN 1.4301 Equiv.

*Classe di resistenza A2-50 Equiv. Vite: JIS 0209 (6g)

Rondelle Rondella elastica JIS B1251
Rondella piatta JIS B1256

S Trattamento superficie Gambo, passivazione

MxP	A	E	C	D	(a)
4x0.7	7	2.8	7.0	10	4.4
5x0.8	8	3.5	8.5	12	5.2
6x1.0	10	4.0	11.5	13	6.3
8x1.25	13	5.5	14.5	18	8.4

(a) è la lunghezza massima (riferimento) tra la superficie della testa e la filettatura completa.



Ordering Example

Cod. comp.

WSET5-10
WSET4-8

Cod. comp.	Tipo	M-L	WSET				WSETS			
			Prezzo unitario	Sconto volumi elevati			Prezzo unitario	Sconto volumi elevati		
			1 - 29 pz.	30 - 99 pz.	100 - 199 pz.	200 - 500 pz.	1 - 29 pz.	30 - 99 pz.	100 - 199 pz.	200 - 500 pz.
	3	- 6								
		8								
		10								
		12								
	4	- 8								
		10								
		12								
		15								
	5	- 8								
		10								
		12								
		15								
	6	- 10								
		12								
		15								
		20								

Cod. comp.	Tipo	M-L	BSET		SBSET		Cod. comp.	Tipo	M-L	BSET		SBSET	
			Prezzo unitario	Sconto volumi elevati	Prezzo unitario	Sconto volumi elevati				Prezzo unitario	Sconto volumi elevati	Prezzo unitario	Sconto volumi elevati
			1 - 99 pz.	100 - 500 pz.	1 - 99 pz.	100 - 500 pz.				1 - 99 pz.	100 - 500 pz.	1 - 99 pz.	100 - 500 pz.
	BSET	4- 8						BSET	6-20				
	SBSET	10						SBSET	25				
		12							30				
		14							35				
		16							40				
		20							45				
		25							50				
		30							55				
		35							60				
		40							65				
		45							70				
		50							75				
	BSET	5-10						BSET	8-12				
	SBSET	12						SBSET	14				
		14							16				
		20							20				
		25							25				
		30							30				
		35							35				
		40							40				
		45							45				
		50							50				
		55							55				
	BSET	6-10						BSET	60				
	SBSET	12						SBSET	65				
		14							70				
		16							75				



Ordering Example