



# OIL-FREE CENTER RAILS

—STANDARD TYPE (COPPER ALLOY)—

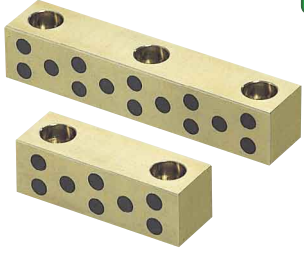


RoHS

■ Mounting bolt hole : 2

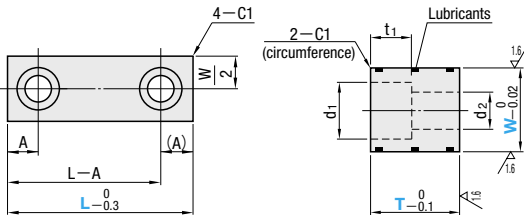

■ Mounting bolt hole : 3

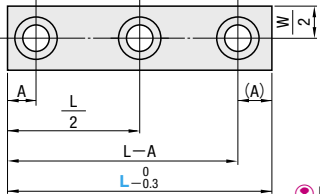

⚠ Keep temperature under 80°C or lower.

Part Number	M			
CGZ	Grade-4 high strength brass (CAC304) (Old JIS: HBsC4) Special solid lubricant embedded			

■ Table for Bolt Hole Size

W	T	d <sub>1</sub>	d <sub>2</sub>	t <sub>1</sub>
15	15	9.5	5.5	6
20	15	11	6.5	7
	20			


Part Number Type	W	T	L				No. of bolt holes	A
			40	50	60	70		
CGZ	15	15	70 80 90 100				2	7.5
			40 50 60 70 80 90				3	
	20	15	100 110				2	10
			120 130 140 150				3	

Order Part Number - T - L

CGZ15 - 15 - 40

Days to Ship Quotation


Price Quotation

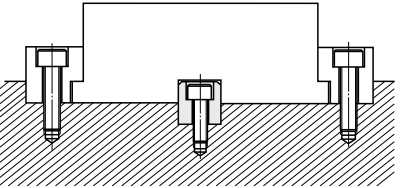Example 

# OIL-FREE CENTER RAILS


—BOLT HOLE PITCH DESIGNATION TYPE (COPPER ALLOY)—

⚠ Non JIS material definition is listed on P.1351 - 1352

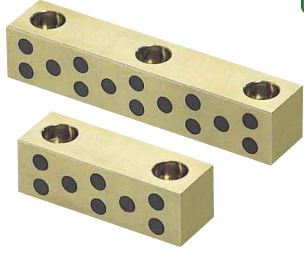


RoHS

■ Mounting bolt hole : 2 2H

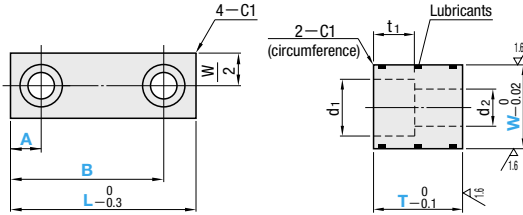

■ Mounting bolt hole : 3 3H

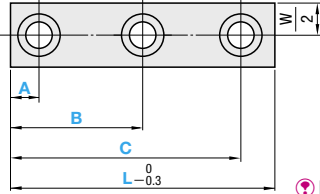

⚠ Keep temperature under 80°C or lower.

Part Number	M			
CGZF-□H	Grade-4 high strength brass (CAC304) (Old JIS: HBsC4) Special solid lubricant embedded			

■ Table for Bolt Hole Size

W	T	d <sub>1</sub>	d <sub>2</sub>	t <sub>1</sub>
15	15	9.5	5.5	6
20	15	11	6.5	7
	20			

Part Number Type	No. (Bolt hole)	W	T Selection	L 10mm increments	Bolt hole pitch 0.5mm increments					
					A		B		C	
					min.	max.	min.	max.	min.	max.
CGZF	2H	15	15	<span style="border: 1px solid black; padding: 1px;">2H</span> 40~70	7	B-11.5	A+11.5	<span style="border: 1px solid black; padding: 1px;">2H</span> L-7	B+11.5	<span style="border: 1px solid black; padding: 1px;">3H</span> L-7
				<span style="border: 1px solid black; padding: 1px;">3H</span> 60~100			<span style="border: 1px solid black; padding: 1px;">3H</span> C-11.5			
	3H	20	15	<span style="border: 1px solid black; padding: 1px;">2H</span> 40~110	7.5	B-13	A+13	<span style="border: 1px solid black; padding: 1px;">2H</span> L-7.5	B+13	<span style="border: 1px solid black; padding: 1px;">3H</span> L-7.5
				<span style="border: 1px solid black; padding: 1px;">3H</span> 80~110						
				<span style="border: 1px solid black; padding: 1px;">3H</span> 120~150						

Order Part Number - T - L - A - B - C

2H CGZF-2H15 - 15 - 70 - A7 - B47

3H CGZF-3H15 - 15 - 100 - A7 - B40 - C90

 

Days to Ship Quotation

Price Quotation

Alterations Part Number - T - L - A - B - (MC)

CGZF-2H15 - 15 - 70 - A13.0 - B52.0 - MC

Quotation

Alteration	Code	Spec.	1Code
	MC	Change to tap hole Details 	<span style="border: 1px solid orange; padding: 2px; font-weight: bold; color: orange;">Quotation</span>